


Raccordi Femmina Filetto metrico Sede 24° con O-Ring per tubi: DIN 20023-4SH EN 856-4SH|SAE 100R13 EN 856-R13|SAE 100R15
Metric Females 24° Cone with O-Ring for Hoses: DIN 20023-4SH EN 856-4SH|SAE 100R13 EN 856-R13|SAE 100R15
Metrisch 24° Dichtkegel mit O-Ring für Schläuche: DIN 20023-4SH EN 856-4SH|SAE 100R13 EN 856-R13|SAE 100R15


ISO 12151-2 (ISO 8434-1)

MDKOS

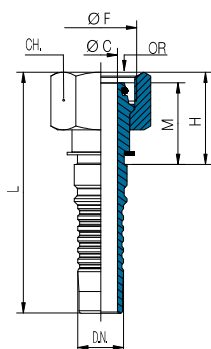


	CODICE Part n° Bestell-Nr.	DN DN DN	Filetto Thread Gewinde	Ø F ø F ø F	DN Tubo DN Hose DN Schlauch	CH	L	Ø C	H	M	OR
NEW b	S 80 41 0 920 019	S 20	M 30x2	3/4"	19	36	102	14	40	34	16x2,5
b	S 80 41 0 925 019	S 25	M 36x2	3/4"	19	46	105,5	14	43,5	37	20x2,5
NEW a	S 80 41 0 925 025	S 25	M 36x2	1"	25	46	113,5	19	39,5	33	20x2,5
b	S 80 41 0 930 025	S 30	M 42x2	1"	25	50	120	19	46	39	25x2,5
NEW b	S 80 41 0 938 032	S 38	M 52x2	1 1/4"	31	60	134,5	25	54,5	44,5	33x2,5
a	S 80 41 0 938 038	S 38	M 52x2	1 1/2"	38	65	140,5	31	49	40	33x2,5

MDKOS 90

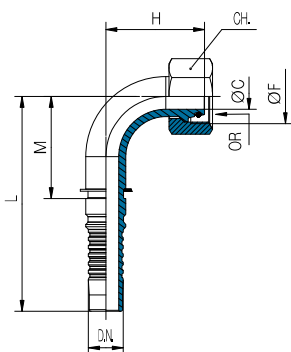

NEW b	S 80 53 0 920 019	S 20	M 30x2	3/4"	19	36	125,5	14	57,5	63,5	16x2,5
b	S 80 53 0 925 019	S 25	M 36x2	3/4"	19	46	125,5	14	62	63,5	20x2,5
NEW a	S 80 53 0 925 025	S 25	M 36x2	1"	25	46	157,5	19	83	83,5	20x2,5
b	S 80 53 0 930 025	S 30	M 42x2	1"	25	50	157,5	19	72,5	83,5	25x2,5
NEW b	S 80 53 0 938 032	S 38	M 52x2	1 1/4"	31	60	182	25	91	102	33x2,5
a	S 80 53 0 938 038	S 38	M 52x2	1 1/2"	38	65	213	31	117	121,5	33x2,5

MDKOS 45

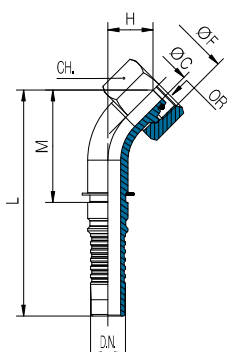

NEW b	S 80 83 0 920 019	S 20	M 30x2	3/4"	19	36	133	14	27	71	16x2,5
b	S 80 83 0 925 019	S 25	M 36x2	3/4"	19	46	136	14	30	74	20x2,5
NEW a	S 80 83 0 925 025	S 25	M 36x2	1"	25	46	170	19	40	96	20x2,5
b	S 80 83 0 930 025	S 30	M 42x2	1"	25	50	164	19	34,5	90	25x2,5
NEW b	S 80 83 0 938 032	S 38	M 52x2	1 1/4"	31	60	192,5	25	41	112,5	33x2,5
a	S 80 83 0 938 038	S 38	M 52x2	1 1/2"	38	65	228	31	55,5	136,5	33x2,5

a: dado pressato
b: dado

a: crimped nut
b: union nut

a: verkrimpde Überwurfmutter
b: Überwurfmutter