


Female connectors

Female thread: BSPP thread, cylindrical

Tube coupling: VOSS Lok⁴⁰

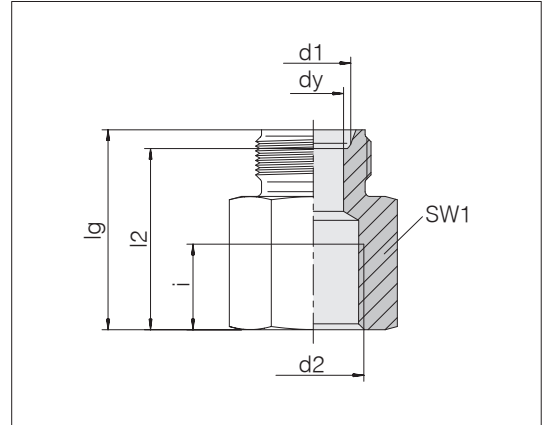

Tube OD d1	d2 BSPP	dy	lg	l2	SW1	i	kg/100 ca.	Order-No.	Designation
6	G 1/8 A	4.5	25.5	22.9	17	8.5	2.9	7005764400	40-S-6-IG1/8-SST
8	G 1/4 A	6.5	31.5	28.8	19	12.5	4.3	7005764300	40-S-8-IG1/4-SST
10	G 1/4 A	8	31.5	28.5	19	12.5	4.8	7005764200	40-S-10-IG1/4-SST
12	G 3/8 A	10	33.5	30.4	22	12.5	6.5	7005764100	40-S-12-IG3/8-SST
14	G 1/2 A	11.5	36	32.8	27	15	10.5	7005764000	40-S-14-IG1/2-SST
15	G 1/2 A	12	36	32.7	27	15	10.3	7005763900	40-S-15-IG1/2-SST
16	G 1/2 A	13	36	32.5	27	15	10.0	7005763800	40-S-16-IG1/2-SST
18	G 1/2 A	15	38	34.4	27	15	10.9	7005763700	40-S-18-IG1/2-SST
20	G 3/4 A	16	40.5	36.8	36	16.5	21.1	7005763600	40-S-20-IG3/4-SST
22	G 3/4 A	18	40.5	36.5	36	16.5	20.1	7005763500	40-S-22-IG3/4-SST