


Caps

For blind closing of VOSS Lok⁴⁰ tube couplings

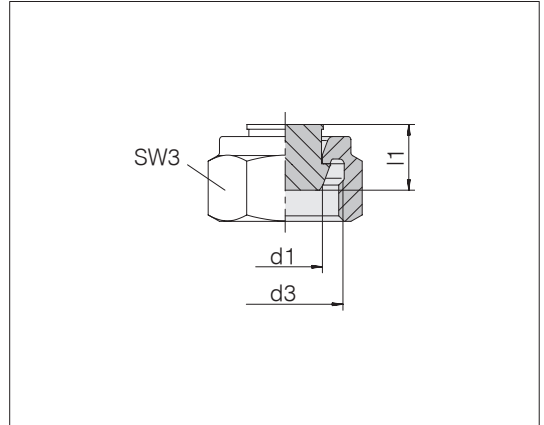

Tube OD d1	d3 UN/UNF	l1	SW3	kg/100 ca.	Order-No.	Designation
6	7/16 - 20 UNF	10	14	1.2	7001215400	40-PLC-6-SST
8	1/2 - 20 UNF	10.6	16	1.7	7001215500	40-PLC-8-SST
10	5/8 - 20 UN	11.4	19	2.4	7001215600	40-PLC-10-SST
12	3/4 - 20 UNEF	12	22	3.2	7001215700	40-PLC-12-SST
14	7/8 - 20 UNEF	12.1	25	4.0	7001215800	40-PLC-14-SST
15	7/8 - 20 UNEF	12.3	25	4.3	7001215900	40-PLC-15-SST
16	7/8 - 20 UNEF	12.4	25	4.4	7001216000	40-PLC-16-SST
18	1 - 20 UNEF	12.5	30	6.7	7001216100	40-PLC-18-SST
20	1 1/8 - 20 UN	12.7	32	7.3	7001216200	40-PLC-20-SST
22	1 1/8 - 20 UN	12.9	32	7.9	7001216300	40-PLC-22-SST

The union nuts are silver plated to reduce the assembly forces inside.